




4-Position Junction W/ Bracket, 15kV

By Hubbell
Catalog # [215J4B](#)

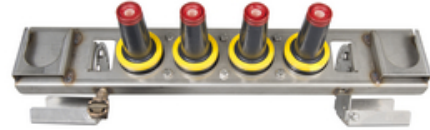

Load Break Junction, 4-Position, 200 Amp, 15 kV, Bracket

Features

- Meets or Exceeds IEEE Std. 386 and IEEE Std. 592 requirements
- Interchangeable with other products meeting the same requirements
- Fully shielded, insulated and submersible

General

EU RoHS Indicator	No
Mounting Type	Brackets
Number of Positions	4
Type	200Amp Load Break
UPC	096359392590

Dimensions

Dimensions	26.2 in x 8.500 in x 10.00 in
Height	10 in
Length	26.2 in
Weight	12.78 lb
Width	8.5 in

Electrical Ratings

AC Withstand Voltage (1 min)	34 kV
Basic Impulse Level	95 kV
Corona Extinction (3pC)	11 kV
Current Rating	200 A
kV Class	15 kV

Logistics

Pallet Quantity	25
Standard Package	1

Product Assets

[Catalogs - Cable Accessories](#)
[Installation Manuals - 15kV & 25/28kV 200 Amp Junctions](#)
[Sales Drawings - 200A 15kV JUNCTION](#)
[SDS - VERSILUBE G661 SILICONE COMPOUND](#)
[Test Documents - ANSI/IEEE Design Test Report - 15kV 200A Loadbreak Separable Connectors](#)
[Video - Grease Best PRactices](#)
[Video - 200A Loadbreak Elbow Fault Closure](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved
HubbellBrand-215J4B-SPEC-EN | REV 6/2024