


KUL Bonding Clamp, One Bare Groove

By Hubbell Power Systems
Catalog # [KUL14716BG](#)

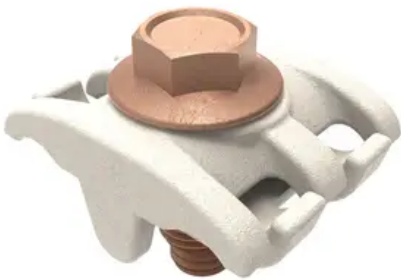

Used to Bond 1/4" to 7/16" Strand to #8 to 2/0 Copper Wire

*Representative Image

Features

- Tin plated for corrosion protection with one bare groove
- High strength copper alloy
- Half-inch hex head silicon bronze bolt

Application

Bonding

General

Bolt Head Type	Hex
Bolt Installation Torque (Recommended)	180 in-lbs
Catalog Number	KUL14716BG
Material	Copper Alloy
Material - Bolt	Silicon Bronze
Plating	Yes
Product Category	Communications Connectors
UPC	096359640301

Dimensions

Bolt Diameter	0.31
Dimensions	1.410 in x 1.130 in x 0.460 in

Height	0.46 in
Length	1.41 in
Weight	0.2 lb
Width	1.13 in

Conductor Related

Conductor Diameter - Maximum	0.365
Conductor Diameter - Minimum	0.128
Conductor Diameter Range	0.128 - 0.365
Conductor Type	Copper Wire
Messenger Diameter - Maximum	0.438 in
Messenger Diameter - Minimum	0.25 in

Certifications And Compliance

UL Listed	Yes
-----------	-----

Product Assets

[Literature - KUL CLAMP](#)
[Sales Drawings - CC-23639](#)
[Specifications - KUL14716BG](#)