


Dome Closure 570 Isolated Ground,
Grommets

By Hubbell Power Systems
Catalog # [PSCI570SG](#)

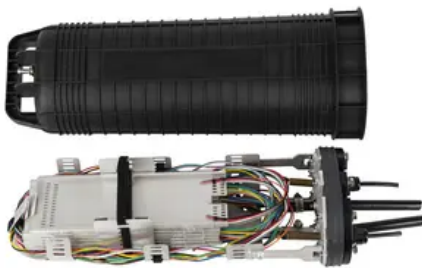

Dome Closure 570 Isolated Ground, Grommets

Features

- Splice capacity: 432 single fusion / 1152 mass fusion
- Backbone cable ports accept up to .750" OD
- Lateral cable ports accept up to .625" OD
- 2 Grommet bags and stand offs for butt splice included
- Additional cables can be added with cable build out kit

General

Catalog Number	PSCI570SG
Diameter - Cable for Backbone	0.750"
Ports - Maximum	
Diameter - Cable for Lateral	0.625"
Ports - Maximum	
Number Of Ports	6
Number of Trays - Maximum	8
Single Fusion Splice Capacity - Maximum	432
UPC	096359715849

Dimensions

Dimensions	23 in x 8 in x 5.5 in
Height	5.5 in
Length	23 in
Weight	11 lb
Width	8 in

Certifications And Compliance

Buy America(n) Qualified	TAA Compliant (All status valid till December 2024)
--------------------------	---

Logistics

Standard Package	1
------------------	---

Product Assets

[Catalogs - Fiber Splice Closures](#)
[Installation Manuals - TD09169E ADSS and Isolated G Series Inst Literature - HUBBELL® 570 GROMMET SPLICE CLOSURE](#)
[Sales Drawings - SACI570SG](#)
[Specifications - PSCI570SG](#)
[Video - Hubbell Power Systems 350 & 570G Fiber Optic Splice Closures](#)