




# HC14193221512 TYPE 716 1600A DC CONTACTOR.

By Hubbell Industrial Controls  
Catalog # [HC14193221512](#)

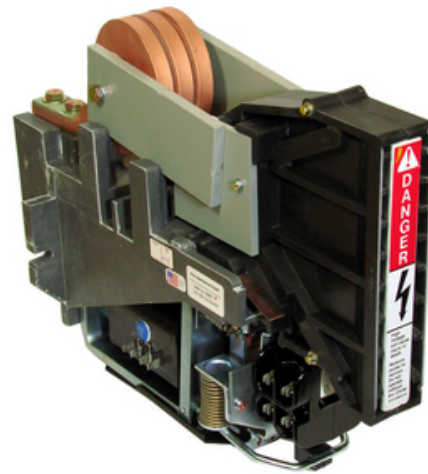

TYPE 716, 1600A DC CONTACTOR

## General

Auxiliary Contacts	2 NO & 2 NC
DC Coil Voltage	12
Maximum break current	2400
Maximum interrupting capacity	2400
Maximum make current	10,000
Mounting Method	Mounts on 3 in. wide support with three 3/8 in. screws
Operating Temperature Range Celcius	20
Series	716
Through current capability	30,000
Type	Definite Purpose

## Dimensions

Weight	27 lb
--------	-------

## Electrical Ratings

Amperage Rating	1600 A
Current / Amperage Rating	1600 A
Maximum Current Rating Amps Continuous	1600 Amps @ 40°C ambient
Operating Voltage	1500
Resistance	3.1
Voltage Rating Description	1500 V

## Product Assets

[Catalogs - 42716 1600 Amp DC Contactor Catalog](#)  
[Catalogs - 100D DC Devices Brochure](#)  
[Installation Manuals - DC Contactor Type 716 Installation, Maintenance, Parts List](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.  
ICD-HC14193221512-SPEC-EN | REV 1/2024