




HKH Series 20A Factory Sealed Contact Block - NC Contact - Din Rail Mount

By Killark
Catalog # [HKH1NC20D](#)

HKH 20A Factory Sealed Contact Block - NC Contact - Din Rail Mount

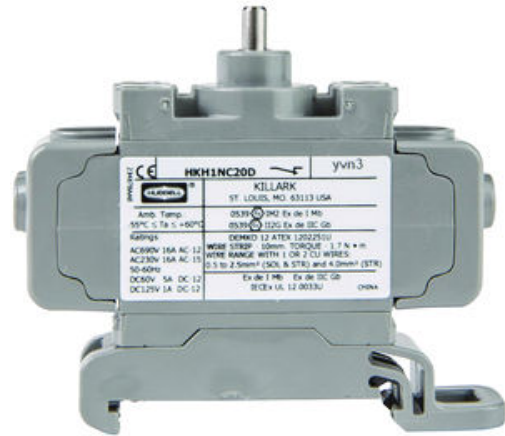

*Representative Image

Features

- Explosion Protected Din Rail contact block 690VAC N.O. & N.C. capable of 20 Amps for Switching Duty and HP Ratings up to 1HP.

Application

Contact block shall be installed in a Class I, Zone 1, AEx e II/Ex e IIC increased safety enclosure with a minimum IP54 rating or a Class I, Zone 1, AEx d IIC/Zone 21, Aex tb minimum IP64 rating, where the suitability is determined in the end application.

General

Action	Momentary
EU RoHS Indicator	Contact Manufacturer
Horsepower - Maximum	1
Operating Temperature Range Celcius	-40°C to 55°C
Series	HKH
UPC	783936092638

Electrical Ratings

Amperage Rating	20 A
Frequency Rating	50/60 Hz
Voltage Rating	24-690 AC/DC V

Certifications and Compliance

ATEX File Number	120225IU
Hazardous Rating(s)	<ul style="list-style-type: none"> • Class I, Division 2, Groups A, B, C, D • Class I, Zones 1 & 2
IECEX File Number	12.0033U
UL File Number	E12379

Logistics

Carton Quantity	20
-----------------	----

Product Assets

- [Catalogs - Killark Catalog](#)
- [Certifications - HKH Contact Blocks Attestation of Conformity](#)
- [Certifications - HKH Series Contact Blocks IECEx Certification](#)
- [Certifications - HKH Series Contact Blocks UL Certification](#)
- [Certifications - HKH Series Contact Blocks ATEX Certificate](#)
- [Customer Notices - Prop 65 Notice](#)
- [Installation Manuals - HKH Series Contact Blocks IOM K1402](#)



A proud member of the Hubbell Family.