




# G Series - Long Momentary Contact Single Push Button Operator -Green Button With "Reset"/Blank Nameplate - 1NO/1NC Contact Rating

By Killark  
Catalog # [GO1-GX3C N34](#)

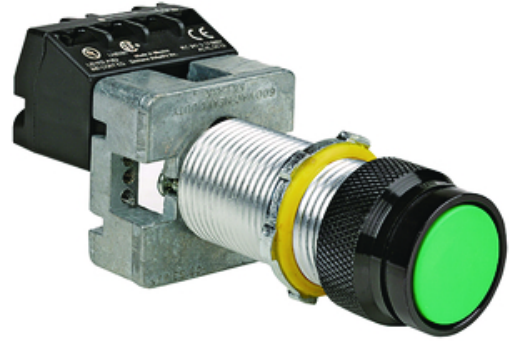

\*Representative Image

G Series - Aluminum Long Momentary Contact Single Push Button Operator -Green Button With "Reset"/Blank Nameplate - 1NO/1NC Contact Rating.

## Features

- Operators are all aluminum except for certain movable parts which are stainless steel.
- All other parts such as screws are either stainless steel or plated steel.
- Threaded bodies are all 3/4"-14 NPSM thread.
- Control stations can be grouped into a single assembly thus reducing installation time and cost.

## Application

G Series custom control panel operators are designed for use in hazardous locations when installed in suitable enclosures such as B7E, EXB, XJB, DB, SWB, and GCS Series boxes and B7, Y7 starter enclosures.

## General

Action	Momentary
Actuator	Single Pushbutton
Ambient Temp. Range	UL: -25 to 40 °C, CSA: -50 to 40 °C, IEC: -20 to 40 °C
EU RoHS Indicator	Contact Manufacturer
Number Of Poles	1
Series	GO
Type	<ul style="list-style-type: none"> <li>• Push Button</li> <li>• Push Button</li> </ul>
UPC	783936221427

## Dimensions

Dimensions	6.75 in x 2.25 in x 2 in
Gross Weight with Packaging	0.62
Height	2 in
Length	6.75 in
Width	2.25 in

## Electrical Ratings

Amperage Rating	10 A
Contact Rating	60A INRUSH @ 120 VAC; 30A INRUSH @ 240 VAC; 15A INRUSH @ 480 VAC; 12A INRUSH @ 600 VAC; 0.55A INRUSH @ 125 VDC; 0.275A INRUSH @ 250 VDC; 6A BREAKING @ 120 VAC; 3A BREAKING @ 240 VAC; 1.5A BREAKING @ 480 VAC; 1.2A BREAKING @ 600 VAC; 0.55A BREAKING @ 125 VDC; 0.275A BREAKING @ 250 VDC; 10A CARRYING @ 120 VAC; 10A CARRYING @ 240 VAC; 10A CARRYING @ 480 VAC; 10A CARRYING @ 600 VAC; 2.5A CARRYING @ 125 VDC; 2.5A CARRYING @ 250 VDC.
Frequency Rating	50/60 Hz

## Certifications and Compliance

CSA File Number	LR11714
Hazardous Rating(s)	<ul style="list-style-type: none"> <li>• Class I, Divisions 1 &amp; 2, Groups B, C, D</li> <li>• Class I, Zones 1 &amp; 2, Groups IIB, IIA</li> <li>• Class II, Divisions 1 &amp; 2, Groups E, F, G</li> <li>• Class III, Divisions 1 &amp; 2</li> </ul>
Nema Rating	3, 4, 4X
UL File Number	E12379

## Product Assets

- [Certifications - GO Series Operators CSA Certificate of Compliance](#)
- [Certifications - G Series Auxiliary Devices UL Certification](#)
- [Customer Notices - Prop 65 Notice](#)
- [Installation Manuals - GO1 & GOL1 Single Pushbutton Operators IOM K1001](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.  
KILL\_CA-G01-GX3C N34-SPEC-EN | REV 1/2024