




LB27SA - 3/4" LB Hub, Aluminum Duraloy 7 Conduit Body

By Killark

Catalog # [LB27SA](#)

3/4" LB Hub, Aluminum Duraloy 7 Conduit Body

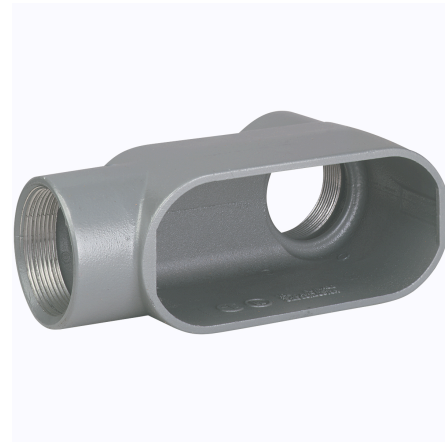

Features

- Enhanced sealing capabilities neoprene sealing gaskets provide a NEMA 3 Seal.
- Suitable for wet locations when used with gaskets.
- High-quality sealing hardware 316 stainless steel cover screws and washers with neoprene gaskets.
- Innovative spring clip design for installation ease and repeat usage.
- For use with threaded rigid conduit steel or aluminum.
- Flat-back design for greater wiring capacity and mounting stability.

Application

To provide access to conductors for pulling, splicing, and maintenance. Threaded for rigid conduit and IMC.

Specifications

EU RoHS Indicator	Contact Manufacturer
CSA File Number	LR11852
Hazardous Rating(s)	Suitable for use in hazardous location applications when installed according to NEC Articles 501.10(b) (Class I, Division 2) or 502.10, 503.10, and 505.15 (Class I Zone 2).
UL File Number	E3397

Configuration

Hub Pattern LB

Dimensions

Hub Size	3/4"
Length	6 in
Gross Weight with Packaging	0.47
Width	2 in
Weight	0.47 lb.
Height	3 in
Dimensions	6 in x 2 in x 3 in

General

Series	Duraloy 7 Series
Color	Gray
Type	Conduit Body
Material	Aluminum, Copper Free (less than 4/10 of 1%)
Finish Type	Powder Epoxy Paint
UPC	783936080017

Logistics

Carton Quantity 5

Product Assets

[Catalog \[English\]](#)

[Installation Manual \[English\]](#)