




EXB-FDS-0303P - EXB-FDS Series, AL Fused Disconnect Switch, Switch Rating 30 -3-Pole - Top Conduit 2", Bottom Conduit 1/2", Wire Size #14-4

By Killark
Catalog # EXB-FDS-0303P

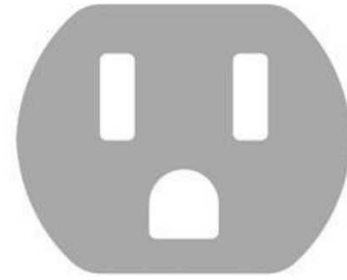

Oh No!
IMAGE COMING SOON

*Representative Image

EXB-FDS Series - Aluminum Fused Disconnect Switch - Switch Rating 30 -3-Pole - Top Conduit 2 Inch - Bottom Conduit 1/2 Inch - Wire Size #14-4

Application

- EXB-NFD Series hinged cover disconnect switches are used: in locations made hazardous due to the presence of flammable gasses or vapors or ignitable dusts, fibers, and flyings
- outdoors or indoors in damp, wet, and dirty locations
- or in areas where frequent washdowns, heavy rain, or water spray routinely occurs.

General

Actuator	Handle
Catalog Number	EXB-FDS-0303P
EU RoHS Indicator	Contact Manufacturer
Enclosure Type	Bolted
Material	Aluminum, Copper Free (less than 4/10 of 1%)
Mounting Type	Wall
Number Of Poles	3
Operating Temperature Celcius Max	40 Degree
Series	EXB-FDS
Size	8" x 10" x 6"
Type	Aluminum Fused Disconnect Switch
UPC	783936012148

Dimensions

Depth	9.875
Dimensions	14.06 in x 12.3125 in x 14.3125 in
Gross Weight with Packaging	40

Height	14.3125 in
Length	14.06 in
Weight	48 lb
Width	12.3125 in

Electrical Ratings

Amperage Rating	30 A
Frequency Rating	60 Hz
Primary Voltage	600 VAC

Conductor Related

Number Of Wires	4
-----------------	---

Certifications And Compliance

ATEX File Number	PTB 07 ATEX 1024x
CSA File Number	LR11716
Hazardous Rating(s)	<ul style="list-style-type: none"> • Class I, Divisions 1 & 2, Groups B, C, D • Class I, Zones 1 & 2, Groups IIB+H2, IIA • Class II, Divisions 1 & 2, Groups E, F, G • Class III, Divisions 1 & 2
Nema Rating	3, 4, 4X, 7(B, C, D), 9(E, F, G)
UL File Number	E10514 / E83969 / E12379

Product Assets

- [Catalogs - Killark Catalog](#)
- [Customer Notices - Prop 65 Notice](#)
- [Installation Manuals - EXB/LT-FDS & NFD IOM K1517](#)

