




# EXB-NFD-2003P - EXB-NFD Series, 200 Amp 3-Pole , Non-Fused Disconnect Switch

By Killark  
Catalog # [EXB-NFD-2003P](#)

EXB-NFD Series, 200 Amp 3-Pole , Non-Fused Disconnect Switch

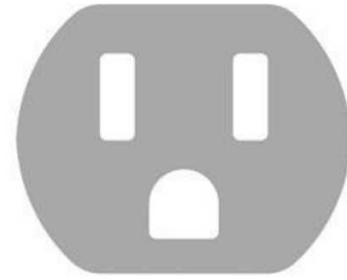

**Oh No!**  
IMAGE COMING SOON

\*Representative Image

## General

Catalog Number	EXB-NFD-2003P
EU RoHS Indicator	Contact Manufacturer
Material	Aluminum, Copper Free (less than 4/10 of 1%)
Mounting Type	Wall
Operating Temperature Celcius Max	40 Degree
Series	EXB-NFD
Size	12" x 24" x 8"
Type	Non-Fused Disconnect
UPC	783936132310

## Dimensions

Depth	15.9375
Height	28.375 in
Weight	170 lb
Width	16.375 in

## Electrical Ratings

Frequency Rating	60 Hz
Primary Voltage	600 VAC

## Certifications And Compliance

ATEX File Number	PTB 07 ATEX 1024x
CSA File Number	LR11716
Hazardous Rating(s)	<ul style="list-style-type: none"> <li>Class I, Divisions 1 &amp; 2, Groups B, C, D</li> <li>Class I, Zones 1 &amp; 2, Groups IIB+H2, IIA</li> <li>Class II, Divisions 1 &amp; 2, Groups E, F, G</li> <li>Class III, Divisions 1 &amp; 2</li> </ul>
Nema Rating	3, 4, 4X, 7(B, C, D), 9(E, F, G)
UL File Number	E10514 / E83969 / E12379

## Product Assets

- [Catalogs - Killark Catalog](#)
- [Customer Notices - Prop 65 Notice](#)
- [Installation Manuals - EXB/LT-FDS & NFD IOM K1517](#)
- [Installation Manuals - EXB Series Drilling & Tapping IOM K1156](#)