




COMBO (RIGID/IMC OR EMT) BODIES AND ASSEMBLIES

Threaded Conduit Fittings: LB Body Only
1" Rigid LB Type Body

C13.1

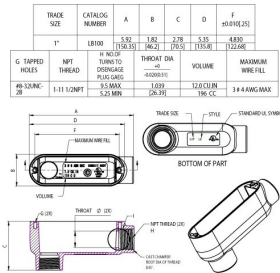

Catalog #: LB100

APPLICATIONS

For use with threaded Rigid/IMC conduit, for pulling access or to split a run into multiple directions.
N/A

PRODUCT FEATURES

Durable die cast aluminum construction
Premium powder coat finish
Combination head screw

CULUS

Listed

NEMA

NEMA 3R Rated

NEC

2014 NEC Compliant

GENERAL PRODUCT INFORMATION

Trade Size: 1"
Description Table: 1" Rigid LB Type Body

PACKAGING

Package Type: Carton
Std. Pkg.: 5
Ship Carton Qty.: 25
Product UPC-A Labeled: Yes
Weight (Lbs. Per/C): 38
Ship Carton Length (in.): 21.65
Ship Carton Width (in.): 8.66
Ship Carton Height (in.): 6.89
Ctn Weight (Lbs.): 12.13
Pallet Qty: 1250
UPC Number: 050169816721
I2of5: 50050169816726