




COMBO (RIGID/IMC OR EMT) BODIES AND ASSEMBLIES

Threaded Conduit Fittings: LR Body Only
1/2" Rigid LR Type Body

C13.1

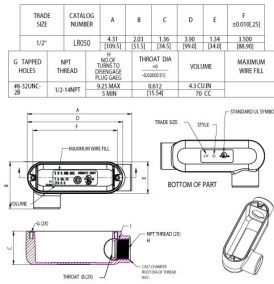

Catalog #: LR050

APPLICATIONS

For use with threaded Rigid/IMC conduit, for pulling access or to split a run into multiple directions.
N/A

PRODUCT FEATURES

Durable die cast aluminum construction
Premium powder coat finish
Combination head screw

CULUS

Listed

NEMA

NEMA 3R Rated

NEC

2014 NEC Compliant

GENERAL PRODUCT INFORMATION

Trade Size: 1/2"
Description Table: 1/2" Rigid LR Type Body

PACKAGING

Package Type: Carton
Std. Pkg.: 10
Ship Carton Qty.: 100
Product UPC-A Labeled: Yes
Weight (Lbs. Per/C): 20
Ship Carton Length (in.): 20.87
Ship Carton Width (in.): 11.81
Ship Carton Height (in.): 9.84
Ctn Weight (Lbs.): 25.79
Pallet Qty: 2400
UPC Number: 050169816905
I2of5: 50050169816900