




COMBO (RIGID/IMC OR EMT) BODIES AND ASSEMBLIES

**Threaded Conduit Fittings: LR Body Only
2" Rigid LR Type Body**

C13.1

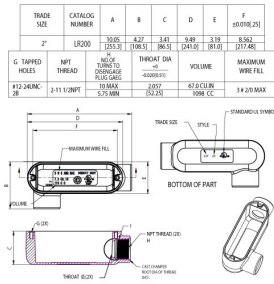

Catalog #: LR200

APPLICATIONS

For use with threaded Rigid/IMC conduit, for pulling access or to split a run into multiple directions.
N/A

PRODUCT FEATURES

Durable die cast aluminum construction
Premium powder coat finish
Combination head screw

CULUS

Listed

NEMA

NEMA 3R Rated

NEC

2014 NEC Compliant

GENERAL PRODUCT INFORMATION

Trade Size: 2"
Description Table: 2" Rigid LR Type Body

PACKAGING

Package Type: Carton
Std. Pkg.: 1
Ship Carton Qty.: 5
Product UPC-A Labeled: Yes
Weight (Lbs. Per/C): 150
Ship Carton Length (in.): 21.85
Ship Carton Width (in.): 11.61
Ship Carton Height (in.): 5.91
Ctn Weight (Lbs.): 11.24
Pallet Qty: 180
UPC Number: 050169816950
I2of5: 50050169816955