


LWTE14-1000

by CMC

Catalog ID: LWTE14-1000

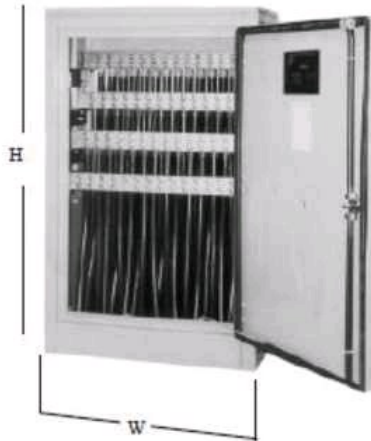

Wall mounted termination enclosures, Three-Phase, NEMA 3R (rain-proof), 600 Volt Rated

- Aluminum mechanical bar connector eliminates compression tools, lugs and bolt assemblies
- Aluminum enclosure is lightweight, low maintenance and has excellent corrosion resistance
- Ample working space, allowing for easier termination with a removable swinging door
- All-welded construction: welds and seams are ground smooth
- Manufactured to meet or exceed ANSI C57-12.28 for wall-mount equipment enclosure integrity
- Three-point positive latch mechanism (secured with a captive and recessed penta-head bolt) and shielded padlock shackle
- Finish meets or exceeds proposed EEI paint specification
- Finish is gray, oven cured powder coat
- All mounting hardware is 18-8 stainless steel

Product Details

General

Material	Aluminum
UPC	192663111909

Dimensions

Depth	16 in
Height	51 in
Width	32 in

Electrical Ratings

Voltage Rating	600 V
----------------	-------

Conductor Related

Conductor Range	1000 Kcmil-#1/0 AWG
Number Of Conductors	14

Certifications and Compliance

Certification - CSA Approved	No
Certification - UL Recognized	Yes
RUS Listed Reference	No



CONNECTOR MANUFACTURING COMPANY
3501 Symmes Road
Hamilton, Ohio 45015 - 1369
513 - 860 - 4455(Press 2 for Customer Service and Sales)
To email customer Service: [jrex @cmclugs.com](mailto:jrex@cmclugs.com)

