


# LWTE21-500

by CMC  
Catalog ID: LWTE21-500

Wall mounted termination enclosures, Three-Phase,  
NEMA 3R (rain-proof), 600 Volt Rated

- Aluminum mechanical bar connector eliminates compression tools, lugs and bolt assemblies
- Aluminum enclosure is lightweight, low maintenance and has excellent corrosion resistance
- Ample working space, allowing for easier termination with a removable swinging door
- All-welded construction: welds and seams are ground smooth
- Manufactured to meet or exceed ANSI C57-12.28 for wall-mount equipment enclosure integrity
- Three-point positive latch mechanism (secured with a captive and recessed penta-head bolt) and shielded padlock shackle
- Finish meets or exceeds proposed EEI paint specification
- Finish is gray, oven cured powder coat
- All mounting hardware is 18-8 stainless steel

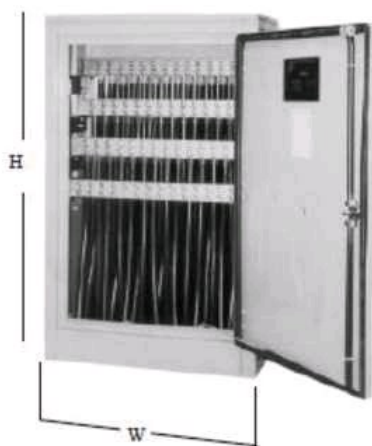

## Product Details

### General

Material	Aluminum
UPC	192663111848

### Dimensions

Depth	16 in
Height	51 in
Width	32 in

### Electrical Ratings

Voltage Rating	600 V
----------------	-------

### Conductor Related

Conductor Range	500 Kcmil - #10 AWG
Number Of Conductors	21

Certifications and Compliance

Certification - CSA Approved	No
Certification - UL Recognized	Yes
RUS Listed Reference	No



**CONNECTOR MANUFACTURING COMPANY**  
3501 Symmes Road  
Hamilton, Ohio 45015 - 1369  
513 - 860 - 4455(Press 2 for Customer Service and Sales)  
To email customer Service: [jrex @cmclugs.com](mailto:jrex@cmclugs.com)

