


NPP4-500I

by CMC
Catalog ID: NPP4-500I

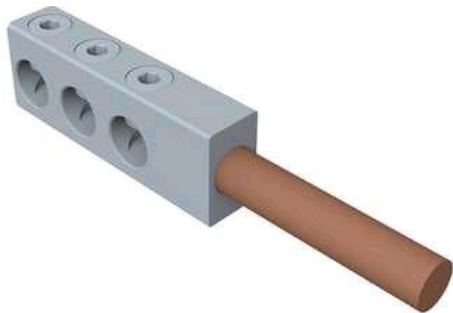

- Transformer eyebolt connectors, dual-rated connectors for aluminum or copper conductors
- Clear plated for low-contact resistance.
 - Fully tested to ANSI C119.4 for Class ‘A’ connectors.
 - For installation on equipment secondary transformers.
 - Stud is electro-tin plated.
 - Supplied with aluminum radial-tipped set-screws.
 - Connector fabricated from 6061-T6 aluminum alloy for conductivity and strength.
 - Includes CO-OX oxide inhibitor in all conductor holes.
 - Each unit individually wrapped and labeled for ease of identification and cleanliness.
 - For installation, CMC® recommends the use of a 9” insulated Allen wrench.

Product Details

General

Material	Aluminum Alloy, 6061-T6
Type	Adapters
UPC	192663083015

Dimensions

Diameter - Stud	0.75 in
Height	1.63 in
Length	5.93 in
Stud Inside Diameter	0.75 in
Width	1 in

Electrical Ratings

Voltage Rating	600 V
----------------	-------

Conductor Related

Conductor Range	500 Kcmil - #10 AWG
Number Of Conductors	4



CONNECTOR MANUFACTURING COMPANY

3501 Symmes Road
Hamilton, Ohio 45015 - 1369
513 - 860 - 4455(Press 2 for Customer Service and Sales)
To email customer Service: [jrex @cmclugs.com](mailto:jrex@cmclugs.com)

