




Copper Solutions, Cable, NEXTSPEED, 10GBE, Plenum Rated, Spool, Green

By Hubbell Premise Wiring
Catalog # [C6ASPGN](#)

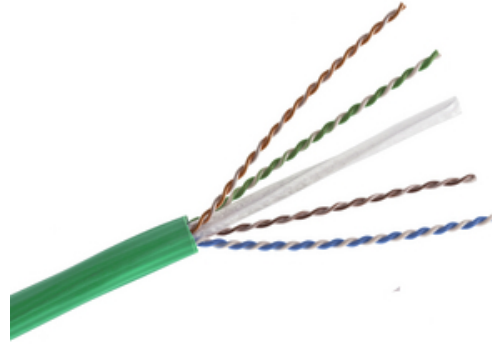

Copper Solutions, Cable, NEXTSPEED, 10GBE, Plenum Rated, Spool, Green

Application

Plenum

General

Construction	Copper/Insulation Eccentricity Shall Be 90% Minimum
Data Transfer Rate	10GbE
EU RoHS Indicator	No
Item Type	NEXTSPEED Category 6A UTP Cable
Material - Jacket	Low Smoke PVC
OEM Brand Name	Hubbell Premise Wiring
Temperature Rating	-20oC to +50oC (-4oF to +122oF)
UPC	662620201962

Electrical Ratings

Capacitance	5.6 nF/100 Meters @ 1 kHz
Impedance	100

Conductor Related

Conductor Size	#23 AWG
Conductor Type	Solid Bare Copper
Nema Color	Green
Pairs Or Conductor	4-Pair

Logistics

Carton Quantity	1000
-----------------	------

Product Assets

[Catalog Page - PREM E4 Catalog Page](#)
[Catalogs - HPW CATALOG_2023_FULL](#)
[Literature - Catch the Wi-Fi 6 Wave](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
PREM-C6ASPGN-SPEC-EN | REV 7/2023