


HUBBELL

Premise Wiring

Cable, SPEEDGAIN, Cat 6, Plenum, Spool, 550Mhz, Green

By Hubbell Premise Wiring
Catalog # [C6ESPGN](#)

Cable, NEXTSPEED 6E/550MHZ, Plenum/Spool, Green

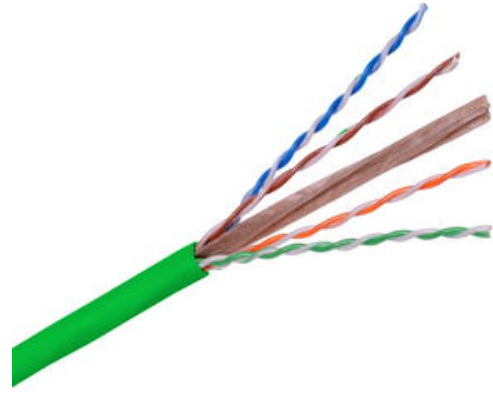

General

Application	Plenum
Catalog Number	C6ESPGN
Construction	Copper/Insulation Eccentricity Shall Be 90% Minimum
Data Transfer Rate	1GbE, Limited 10GbE
EU RoHS Indicator	Yes
Item Type	NEXTSPEED Category 6 UTP Cable
Material - Jacket	Low Smoke PVC
OEM Brand Name	Hubbell Premise Wiring
Temperature Rating	-20oC to +50oC (-4oF to +122oF)
UPC	662620201764

Electrical Ratings

Capacitance	5.6 nF/100 Meters @ 1 kHz
Impedance	100

Conductor Related

Conductor Size	#23 AWG
Conductor Type	Solid Bare Copper
Nema Color	Green
Pairs Or Conductor	4-Pair

Logistics

Carton Quantity	2000
-----------------	------

Product Assets

- [Catalog Page - PREM E5 CatalogPage](#)
- [Catalogs - Premise Wiring Catalog](#)
- [Customer Notices - Prop 65 Notice](#)
- [Literature - Healthcare Application Guide](#)