




# Cable, SPEEDGAIN, Cat 6, Riser, Spool, 550Mhz, Green

By Hubbell Premise Wiring  
Catalog # C6ESRGN

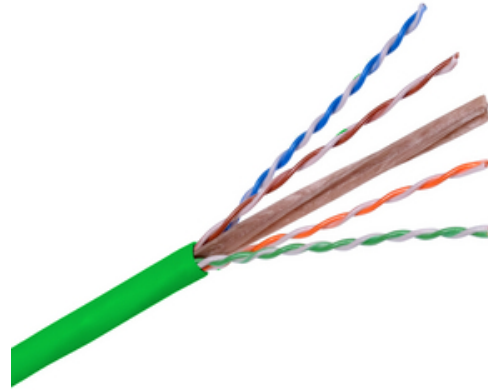

Cable, NEXTSPEED 6E/550MHz, Riser/Spool, Green

## Application

Riser

## General

Construction	Copper/Insulation Eccentricity Shall Be 90% Minimum
Data Transfer Rate	1GbE, Limited 10GbE
EU RoHS Indicator	Yes
Item Type	NEXTSPEED Category 6 UTP Cable
Material - Jacket	PVC
OEM Brand Name	Hubbell Premise Wiring
Temperature Rating	-20oC to +50oC (-4oF to +122oF)
UPC	662620201818

## Electrical Ratings

Capacitance	5.6 nF/100 Meters @ 1 kHz
Impedance	100

## Conductor Related

Conductor Size	#23 AWG
Conductor Type	Solid Bare Copper
Nema Color	Green
Pairs Or Conductor	4-Pair

## Logistics

Carton Quantity	2000
-----------------	------

## Product Assets

[Catalog Page - PREM E5 Catalog Page](#)  
[Catalogs - HPW CATALOG\\_2023\\_FULL](#)  
[Literature - Healthcare Application Guide](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.  
PREM-C6ESRGN-SPEC-EN | REV 7/2023