




Copper Solutions, Cable, Cat6 Enhanced, Riser Rated, Spool, Orange

By Hubbell Premise Wiring
Catalog # [C6ESROR](#)

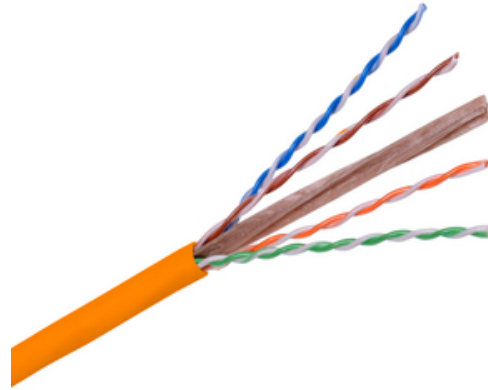

Cable, NEXTSPEED 6E/550MHz, Riser/Spool, Orange

Application

Riser

General

Construction	Copper/Insulation Eccentricity Shall Be 90% Minimum
Data Transfer Rate	1GbE, Limited 10GbE
EU RoHS Indicator	Yes
Item Type	NEXTSPEED Category 6 UTP Cable
Material - Jacket	PVC
OEM Brand Name	Hubbell Premise Wiring
Temperature Rating	-20oC to +50oC (-4oF to +122oF)
UPC	662620288000

Electrical Ratings

Capacitance	5.6 nF/100 Meters @ 1 kHz
Impedance	100

Conductor Related

Conductor Size	#23 AWG
Conductor Type	Solid Bare Copper
Nema Color	Orange
Pairs Or Conductor	4-Pair

Logistics

Carton Quantity	2000
-----------------	------

Product Assets

[Catalog Page - PREM E5 Catalog Page](#)
[Catalogs - HPW CATALOG_2023_FULL](#)
[Literature - Healthcare Application Guide](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
PREM-C6ESROR-SPEC-EN | REV 7/2023