


HUBBELL

Premise Wiring

Copper Solutions, Cable, Cat6, Foil Twisted Pair, 10 Gig, Plenum Rated, Spool, Gray

By Hubbell Premise Wiring
Catalog # [C6FTPSPGY](#)

Copper Solutions, Cable, Cat6, Foil Twisted Pair, 10 Gig, Plenum Rated, Spool, Gray

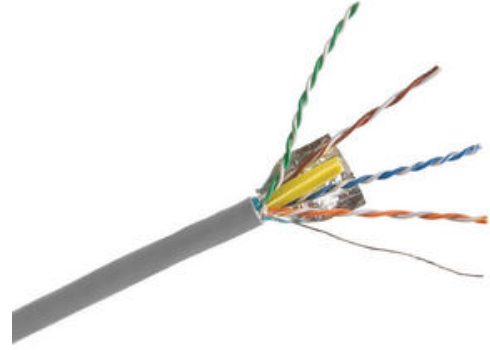

General

Application	Plenum
Catalog Number	C6FTPSPGY
Construction	Copper/Insulation Eccentricity Shall Be 90% Minimum
Data Transfer Rate	1GbE, Limited 10GbE
Debris Shield Type	Foil Tape
EU RoHS Indicator	Yes
Item Type	NEXTSPEED Category 6 FTP Cable
Material - Jacket	Low Smoke PVC
OEM Brand Name	Hubbell Premise Wiring
Temperature Rating	-20oC to +50oC (-4oF to +122oF)
UPC	662620288116

Electrical Ratings

Impedance	100
-----------	-----

Conductor Related

Conductor Size	#23 AWG
Conductor Type	Solid Bare Copper
Nema Color	Gray
Pairs Or Conductor	4-Pair

Logistics

Carton Quantity	1000
-----------------	------

Product Assets

- [Catalog Page - PREM E10 Catalog Page](#)
- [Catalogs - Premise Wiring Catalog](#)
- [Literature - NEXTSPEED® Shielded Category 6 Jack](#)