




Copper Solutions, Cable, Cat6, Foil Twisted Pair, 10 Gig, Plenum Rated, Spool, Pink

By Hubbell Premise Wiring
Catalog # [C6FTPSPPK](#)

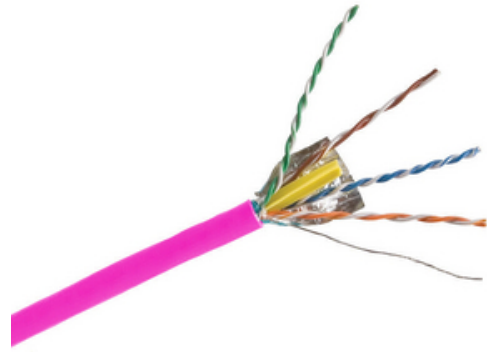

Copper Solutions, Cable, Cat6, Foil Twisted Pair, 10 Gig,
Plenum Rated, Spool, Pink

Application

Plenum

General

Construction	Copper/Insulation Eccentricity Shall Be 90% Minimum
Data Transfer Rate	1GbE, Limited 10GbE
Debris Shield Type	Foil Tape
EU RoHS Indicator	Yes
Item Type	NEXTSPEED Category 6 FTP Cable
Material - Jacket	Low Smoke PVC
OEM Brand Name	Hubbell Premise Wiring
Temperature Rating	-20oC to +50oC (-4oF to +122oF)
UPC	662620211596

Electrical Ratings

Impedance 100

Conductor Related

Conductor Size	#23 AWG
Conductor Type	Solid Bare Copper
Nema Color	Pink
Pairs Or Conductor	4-Pair

Logistics

Carton Quantity 1000

Product Assets



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
PREM-C6FTPSPPK-SPEC-EN | REV 7/2023