


Copper Solutions, Cable, Cat6, Foil
Twisted Pair, 10 Gig, Riser Rated,
Spool, Blue

By Hubbell Premise Wiring
Catalog # C6FTPSRB

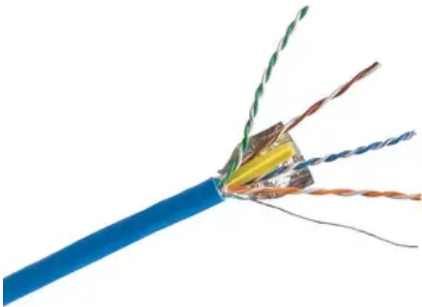

Copper Solutions, Cable, Cat6, Foil Twisted Pair, 10 Gig, Riser
Rated, Spool, Blue

Features

- Cat6
- Foil Twisted Pair
- 10 Gig
- Riser Rated
- Spool

Application

Riser

General

Catalog Number	C6FTPSRB
Construction	Copper/Insulation Eccentricity Shall Be 90% Minimum
Data Transfer Rate	1GbE, Limited 10GbE
Debris Shield Type	Foil Tape
EU RoHS Indicator	Yes
Item Type	NEXTSPEED Category 6 FTP Cable
Material - Jacket	Low Smoke PVC
OEM Brand Name	Hubbell Premise Wiring

Temperature Rating	-20oC to +50oC (-4oF to +122oF)
UPC	662620288154

Electrical Ratings

Impedance	100
-----------	-----

Conductor Related

Conductor Size	#23 AWG
Conductor Type	Solid Bare Copper
Nema Color	Blue
Pairs Or Conductor	4-Pair

Logistics

Carton Quantity	1000
-----------------	------

Product Assets

[Catalog Page - PREM E10 Catalog Page](#)
[Catalogs - Premise Wiring Catalog](#)
[Literature - NEXTSPEED® Shielded Category 6 Jack](#)
[Specifications - C6FTPSRB](#)