




# Copper Solutions, Cable, Cat6, Foil Twisted Pair, 10 Gig, Riser Rated, Spool, Gray

By Hubbell Premise Wiring  
Catalog # [C6FTPSRGY](#)

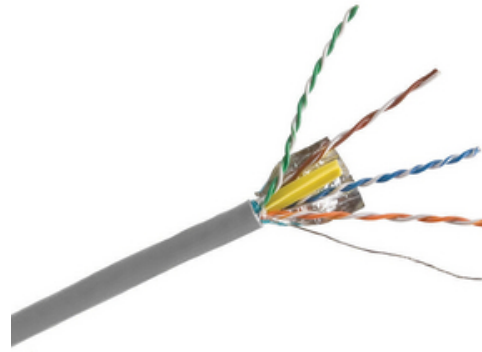

Copper Solutions, Cable, Cat6, Foil Twisted Pair, 10 Gig, Riser Rated, Spool, Gray

## Application

Riser

## General

|                    |   |
|--------------------|---|
| Construction       | Copper/Insulation Eccentricity Shall Be 90% Minimum |
| Data Transfer Rate | 1GbE, Limited 10GbE                                 |
| Debris Shield Type | Foil Tape   |
| EU RoHS Indicator  | Yes   |
| Item Type          | NEXTSPEED Category 6 FTP Cable                      |
| Material - Jacket  | Low Smoke PVC                                       |
| OEM Brand Name     | Hubbell Premise Wiring                              |
| Temperature Rating | -20oC to +50oC (-4oF to +122oF)                     |
| UPC                | 662620288147  |

## Electrical Ratings

Impedance 100

## Conductor Related

|                    |                   |
|--------------------|-------------------|
| Conductor Size     | #23 AWG           |
| Conductor Type     | Solid Bare Copper |
| Nema Color         | Gray              |
| Pairs Or Conductor | 4-Pair            |

## Logistics

Carton Quantity 1000

## Product Assets

[Catalog Page - PREM E10 Catalog Page](#)  
[Catalogs - HPW CATALOG\\_2023\\_FULL](#)  
[Literature - NEXTSPEED® Shielded Category 6 Jack](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.  
PREM-C6FTPSRGY-SPEC-EN | REV 7/2023