


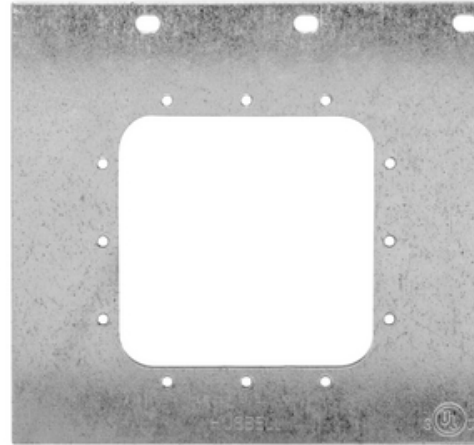

8/10-Gang Series, Mounting Plate, 3-Gang, (1) Opening for Appliance Receptacle

By Hubbell Premise Wiring
Catalog # [FB10MP3GAPP](#)

Concrete, Access, Wood Floorboxes, Recessed, 8/10-Gang Series, Mounting Plate, 3-Gang, (1) Opening for Appliance Receptacle



Features

- Plate for Use in SystemOne 10-Gang Recessed Floorboxes
- 3-Gang- (1) Opening for Appliance Receptacle
- #6 AWG Maximum Device Wire Gauge

Application

For Use in Recessed Floor Box

General

Application - For Use On	Concrete; Raised Access
Color	Metallic
Construction	Stamped
Cover Shape	Rectangle; Round
Cover Type	Rectangle; Round
EU RoHS Indicator	Contact Manufacturer
Material	Pre Galvanized Steel
Mounting Method	Mounts to Box
Mounting Type	Screw Mount
Number of Gang(s)	3-Gang
Series	Recessed - CFB Series
Size	10-Gang
Type	10-Gang Recessed Floor Box Mounting Plates
UPC	783585545882

Certifications and Compliance

Industry Standard(s) cULus

Logistics

Carton Quantity 15

Product Assets

[Catalog Page - PREM R22 Catalog Page](#)
[Catalogs - HPW CATALOG_2023_FULL](#)

Related Products

- [CFB10G55RCR - 8/10-Gang CFB Series Box for Round Covers, 6.25" Minimum Depth of Pour, Corrosion Resistant Paint](#)
- [AFB10G55CHI - 8/10-Gang AFB Series, 5.50" Deep Rectangular Box with Installation Cover, No Knockouts, Chicago Approved](#)
- [CFB10G55R - 8/10-Gang CFB Series Box for Round Covers, 6.25" Minimum Depth of Pour](#)
- [CFB10G55 - 8/10-Gang CFB Series Box for Rectangular Covers, 5.50" Minimum Depth of Pour](#)
- [CFB10G55CR - 8/10-Gang CFB Series Box for Rectangular Covers, 5.50" Minimum Depth of Pour, Corrosion Resistant Paint](#)



A proud member of the Hubbell Family.