

HUBBELL
Premise Wiring

HFCD14 Series Indoor/Outdoor Tight Buffer, 72 strand, I/O Tight Buffer Plenum, OM3, MM, Black Jacket

By Hubbell Premise Wiring
Catalog # [HFCD14072P3BK](#)

HFCD14 Series Indoor/Outdoor Tight Buffer, 72 strand, I/O Tight Buffer Plenum, OM3, MM , Black Jacket

Features

- Multimode Bend-Insensitive Optical Fiber
- E-Z Strip Buffer For Contractor-Friendly Termination
- Compact Cable Diameter Reduces Pathway Congestion
- Premium Fiber For Enhanced Optical Performance

Application

Data Transmission


Specifications

Industry Standard(s) TIA

Conductor

Fiber Size OM3
Fiber Type OM3, MM
Number Of Fibers 72

Current

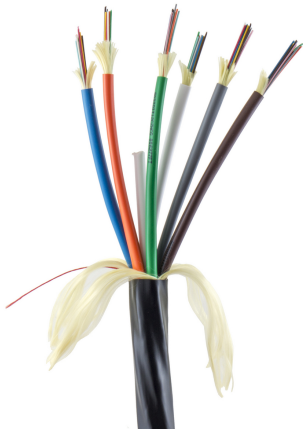

Wavelength 850/1300 Nanometers

General

Sub Brand Fiber Optics
Type Cable
Cable Rating I/O Tight Buffer Plenum
Material - Jacket PVC
UPC 662620555737
Color Black

Operational

Attenuation 3.5/1.5 Db per Kilometer
Temperature Rating 0 Degrees C to 70 Degrees C
Bandwidth 2000 bps

Product Assets

[Catalog \[English\]](#)
[Catalog Page \[English\]](#)
[Catalog Page \[English\]](#)