

HUBBELL  
Premise Wiring

HFCD14 Series Indoor/Outdoor Tight Buffer, 72 strand, I/O Tight Buffer Plenum, OM4, MM, Black Jacket

By Hubbell Premise Wiring  
Catalog # [HFCD14072P4BK](#)

HFCD14 Series Indoor/Outdoor Tight Buffer, 72 strand, I/O Tight Buffer Plenum, OM4, MM , Black Jacket

Features

- Multimode Bend-Insensitive Optical Fiber
- E-Z Strip Buffer For Contractor-Friendly Termination
- Compact Cable Diameter Reduces Pathway Congestion
- Premium Fiber For Enhanced Optical Performance

Application

Data Transmission


Specifications

Industry Standard(s) TIA

Conductor

Fiber Size OM4  
Fiber Type OM4, MM  
Number Of Fibers 72

Current

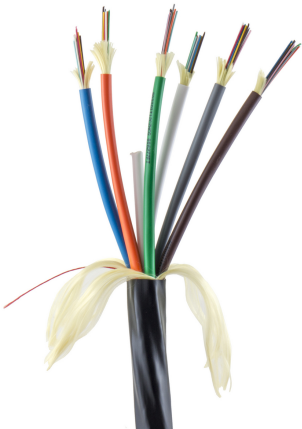

Wavelength 850/1300 Nanometers

General

Sub Brand Fiber Optics  
Type Cable  
Cable Rating I/O Tight Buffer Plenum  
Material - Jacket PVC  
UPC 662620555744  
Color Black

Operational

Attenuation 3.5/1.5 Db per Kilometer  
Temperature Rating 0 Degrees C to 70 Degrees C  
Bandwidth 4000 bps

Product Assets

[Catalog \[English\]](#)  
[Catalog Page \[English\]](#)  
[Catalog Page \[English\]](#)