

HUBBELL
Premise Wiring

HFCD14 Series Indoor/Outdoor Tight Buffer, 72 strand, I/O Tight Buffer Plenum, OS2, SM, Black Jacket

By Hubbell Premise Wiring
Catalog # [HFCD14072PSBK](#)

HFCD14 Series Indoor/Outdoor Tight Buffer, 72 strand, I/O Tight Buffer Plenum, OS2, SM , Black Jacket

Features

- Singlemode Bend-Insensitive Optical Fiber
- E-Z Strip Buffer For Contractor-Friendly Termination
- Compact Cable Diameter Reduces Pathway Congestion
- Premium Fiber For Enhanced Optical Performance

Application

Data Transmission


Specifications

Industry Standard(s) TIA

Conductor

Fiber Size OS2
Fiber Type OS2, SM
Number Of Fibers 72

Current

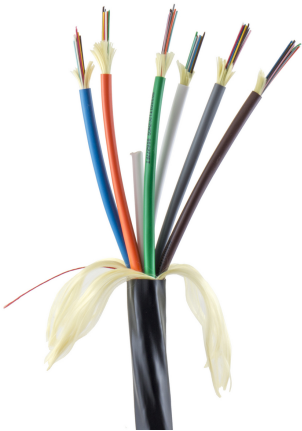

Wavelength 1310/1550 Nanometers

General

Sub Brand Fiber Optics
Type Cable
Cable Rating I/O Tight Buffer Plenum
Material - Jacket PVC
UPC 662620555751
Color Black

Operational

Attenuation 0.5/0.4 Db per Kilometer
Temperature Rating 0 Degrees C to 70 Degrees C

Product Assets

[Catalog \[English\]](#)
[Catalog Page \[English\]](#)
[Catalog Page \[English\]](#)