



# HFCD15 Series Indoor Tight Buffer Distribution, 72 strand, Riser, Armored, OM3, MM , Aqua Jacket

By Hubbell Premise Wiring  
Catalog # [HFCD15072R3](#)

HFCD15 Series Indoor Tight Buffer Distribution, 72 strand, Riser, Armored, OM3, MM , Aqua Jacket.

## Features


- Multimode Bend-Insensitive Optical Fiber
- E-Z Strip Buffer For Contractor-Friendly Termination
- Durable Aluminum Interlock Armor
- Premium Fiber For Enhanced Optical Performance

## Application

Data Transmission

## General

Attenuation	3.5/1.5 Db per Kilometer
Bandwidth	2000 bps
Cable Rating	Riser, Armored
Color	Aqua
Sub Brand	Fiber Optics
Temperature Rating	-10 Degrees C to 70 Degrees C
Type	Cable
UPC	662620343372

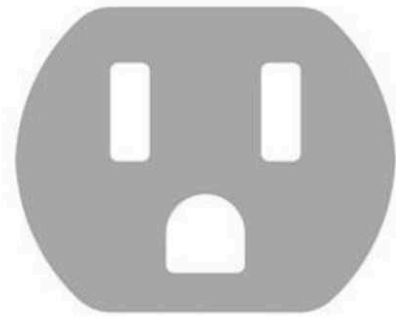

**Oh No!**  
IMAGE COMING SOON

## Electrical Ratings

Wavelength 850/1300 Nanometers

## Conductor Related

Fiber Size OM3  
Fiber Type OM3, MM  
Number Of Fibers 72

## Certifications and Compliance

Industry Standard(s)

- ANSI/ICEA S-83-596
- NFPA-262/UL910/CSA FT-4
- Telcordia GR-409
- TIA-568.3-D

## Product Assets

[Literature - Fiber Optic Cable Guide](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.  
PREM-HFCD15072R3-SPEC-EN | REV 7/2023