

HUBBELL
Premise Wiring

HFCH5 Series - Outdoor Loose Tube, 72 strand, OM3, MM, OSP, Armored Double Jacket, Outdoor Loose Tube, Black Jacket

By Hubbell Premise Wiring
Catalog # [HFCH5072BK3](#)

HFCH5 Series - Outdoor Loose Tube, 72 strand, OM3, MM, OSP, Armored Double Jacket, Outdoor Loose Tube, Black

Features

- Multimode Bend-Insensitive Optical Fiber
- TIA-598-C Colored Buffer Tubes
- Gel-Free Water Blocking Construction
- Robust Design For Enhanced Optical Performance

Application

Data Transmission


Specifications

Industry Standard(s)	• ANSI/ICEA S-87-640 • ANSI/TIA-758-A • Telcordia GR-20 • TIA-568.3-D
----------------------	---

Conductor

Fiber Size	OM3
Fiber Type	OM3, MM
Number Of Fibers	72

Current

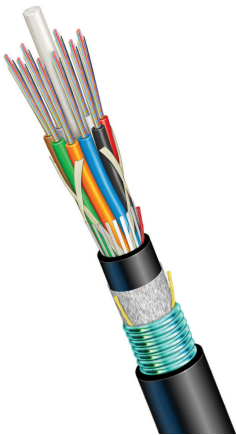

Wavelength	850/1300 Nanometers
General	
Sub Brand	Fiber Optics
Type	Cable
Cable Rating	OSP, Armored Double Jacket
Material - Jacket	MDPE
Specifications	• Armor - Corrugated Steel • Cable Diameter in (mm) - 0.57 (14.5) • Cable Weight (lb/kft) - 131 • Construction - Armored Double Jacket Loose Tube, 6F/Tube, Central Strength Member • Fiber Coating - 250 Micron Acrylate Buffer
UPC	662620606088
Color	Black
Operational	
Temperature Rating	-40 Degrees C to 75 Degrees C
Bandwidth	2000 bps