


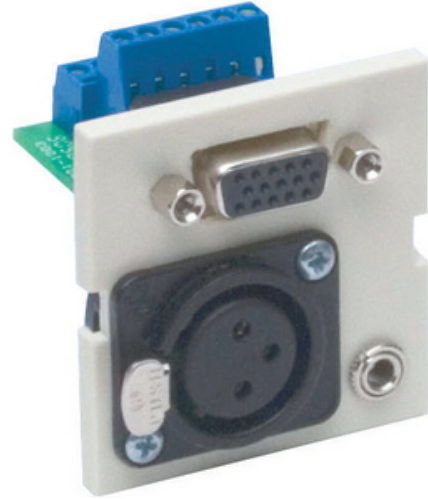

iStation Modules, SVGA with 3.5 MM Stereo Jack and XLR, Screw Terminal, 2-Unit

By Hubbell Premise Wiring
Catalog # [IM153X2OW](#)

iStation Modules, SVGA with 3.5 MM Stereo Jack and XLR, Screw Terminal, 2-Unit



Application

Loaded Pro AV Modules

General

Contact	Beryllium Copper
EU RoHS Indicator	Yes
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Item Type	iSTATION Pro Audio D-Style Connections
Material - Mounting Hardware	Snap-On- Snap-Fit
OEM Brand Name	Hubbell Premise Wiring
Temperature Rating	Per TIA
Type	15-Pin Screw Term
UPC	662620290089

Dimensions

Display Size Standard Sized Product

Electrical Ratings

Connectivity	Plug-N-Play
Contact Resistance	100 Ohm
Withstand Voltage	1000V RMS, 1414V DC

Logistics

Carton Quantity 25

Product Assets

[Literature - Integrating AV Systems](#)
[Sales Drawings - IM153X2OW - PDF](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
PREM-IM153X2OW-SPEC-EN | REV 7/2023