


Fiber H4 Cassette, OS2, LC Quad to 2 MTP,
Blue

By Hubbell Premise Wiring
Catalog # [OCLCQSMH4](#)

Fiber Optic, Cassette Adapter Panel, High Density, H4 Opening, LC to MTP, Single Mode, 24 Fiber, Blue

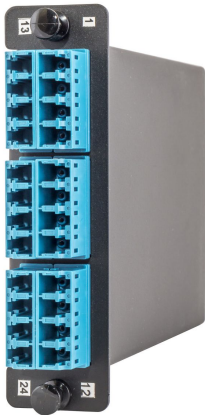

Features

- Compact Universal Design
- Designed for H4 Series 4 across Panels
- Quick and Easy Plug-n-Play Installation

Application

Interconnect

Performance

Optical - Return loss - More than 50dB, Optical - Total insertion loss - Less than 1.1dB (test data included)

Specifications

Industry Standard(s)	• Telcordia GR-326-CORE • TIA-568-C.3 • TIA-604-FOCIS
----------------------	---

Environmental Conditions	Indoor
--------------------------	--------

Conductor

Fiber Size	250 Micron
Fiber Type	OS2

Current

Insertion Loss	0.75 dB Max
Return Loss	55
Connectivity	Cassette

Dimensions

Display Size	4.3" x 1.1"
--------------	-------------

General

Color	Blue
Style	LC-MTP
UPC	662620605418
Material - Mounting Hardware	Snap-In
Item Type	LC Quad to MTP
Sub Brand	OptiChannel
Material	Ceramic

Logistics

Carton Quantity	25
-----------------	----

Operational

Repeatability	0.1 dB
Service Life	500 matings
Temperature Rating	0C to 70C

Product Assets

- [Catalog \[English\]](#)
- [Catalog Page \[English\]](#)
- [Catalog Page \[English\]](#)
- [Catalog Page \[English\]](#)