

Non-Metallic Replacement Cover,
Gray

By Hubbell Premise Wiring
Catalog # [PFBRCGYA](#)


Non-Metallic Replacement Cover

Features

- Top Service Fitting with Prewired 20A Duplex Receptacle
- 2-Installed Cat 6 Hubbell Xcelerator Jacks
- Non-metallic Cover with Painted Aluminum Flange

General

Catalog Number	PFBRCGYA
EU RoHS Indicator	Contact Manufacturer
Finish Type	Gray
Item Type	3" Fire-Rated Poke Through Component
Knockouts	Duplex Flip Covers and (2) 1/2" Diameter Holes for Low Voltage Wiring
Material - Mounting Hardware	Mounting Hardware Included
Number Of Outlets	(1) Duplex Opening and (2) 1/2" Diameter Holes for Low Voltage Wiring
Specifications	<ul style="list-style-type: none">• Carpet Flange - Painted Cast Aluminum/Solid Brass, Brushed and Lacquered• Cover Material - Thermoplastic

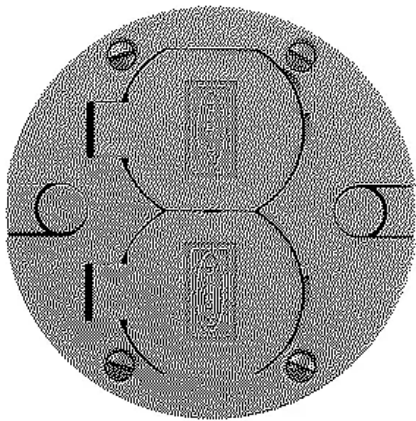

- Floor thickness - 2 1/4 in. to 7 in. (57.2 to 177.8)
 - Housing - Engineered flame-retardant thermoplastic
 - Jack(s) - Low voltage Knockouts Only
- UPC 783585342559

Certifications And Compliance

Industry Standard(s)	<ul style="list-style-type: none">• cULus Listed• Meets ADA Standards• UL 514A Listed
----------------------	---

Logistics

Carton Quantity	10
Pallet Quantity	1320

Product Assets

[Brochures - Floorbox Selection Guide](#)
[Catalog Page - WDK P-32](#) [Catalog Page](#)
[Catalog Page - WDK O-24](#) [Catalog Page](#)
[Catalogs - WDK Catalog Full 2024](#)
[Specifications - PFBRCGYA](#)