


## Rack Mount Kit

### Features

- Provides a Cost-Effective, Front Terminated, High-Density Rack Mount 100 Solution
- Cable Access Openings in Wiring Blocks Allow Cables to be Routed Through the Block Directly to the Point of Termination
- Unique Third Hand Locating Pins Hold Panel in Place on Rack While Installing Screws
- Rolled Edge Construction Provides Superior Strength During Termination

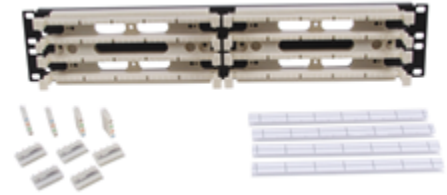

### Ordering Information

Description	Catalog Number	UPC
NEXTSPEED Rack Mount Kit without Cable Management, 200-Pair, 2U Rack Unit, 4-Pair	110RM24NT	662620838625

### Accessories

Hubbell Labeling Solution	XPL11010B
---------------------------	-----------

### Listings

Verified to meet and exceed Category 5E ANSI/TIA/EIA-568-C.2 connecting hardware specifications

### Online Resources

[eCatalog](#)

### Specifications

Panel Material	14 ga. steel
Finish	Durable black powder coat
Organization	Optional rear cable organizer (HC36WF) clips to rear of panel
NEXT Performance	Increased Pair Isolation on 6-110 wiring and connecting blocks provided for superior NEXT performance
Flammability	110 wiring bases and blocks are made of fire-retardant plastic rated UL 94v-0

### Performance

#### Electrical

Mounts directly to 19" EIA-310-D standard rack and cabinet

### Applications

Compatible with Hubbell Labeling Software and laser-printable 110 paper label sheets