

HI-Impact
Category 6 Patch Cords
HI-Impact Cat 6 RJ45 on Both Sides

HUBBELL

Features

- High-Performance Category 6
- IP67 and IP66 Rated for Dust and Liquids
- Durable, Rugged Construction
- Intuitive, Quick Action Mating



Ordering Information

Description	Color	Catalog Number	UPC
HI-Impact Cat 6 RJ45 on Both Ends, 7 feet	Black	HI607EE	662620856025

Listings


UL and cUL Listed
 TIA-568-C.2 Category 6 Component

Specifications

HI-Impact Housing	UV resistant, Valox®, UL 94V-0
-------------------	--------------------------------

Performance

Electrical	Qualified to 150% of 802.3bt PoE Current Level
Mechanical	Vibration: 5g (operational) 10-500Hz Mating Cycle: 750 minimum
Environmental	Ingress Protection: IP67 and IP66 (dust/water) HI-Impact Housing Temperature Range: -25°C to 70°C Corrosion: Resistant to most common chemicals, oils and cleaning agents UV Resistant Housing

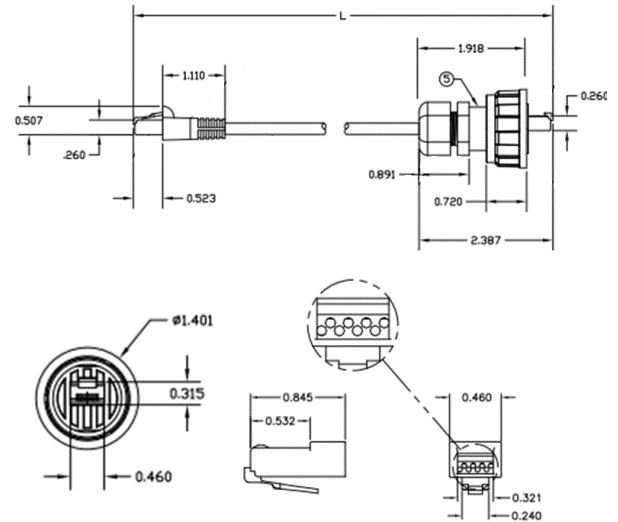

Applications

IEEE 802.3ab 1000GBASE-T
 IEEE 802.3bt 4PPoE Power over Ethernet
 TIA TSB-155 10GbE Over 55 Meters
 Backward compatible with Cat 5E hardware and applications

Accessories

HI-Impact Category 5e Coupler	HI5EC
HI-Impact Category 6 Connector	HI6
HI-Impact Category 6 Coupler	HI6C

Online Resources

Customer Use Drawing
 eCatalog