

- RJ-25 USOC (RJ-25) Jack
- Exclusive 1-Punch Termination Reduces Termination Time by 75%
- Mating Cycles Exceed Industry Standard by Four Times
- Bulk Packaging Reduces Excess Waste on the Job

### Features

- HPW Icon compatible
- IDC towers have an inner blade to assist in pair splitting without performance disruption.
- Small form factor allows more jacks in devices without restriction or constraint.

### Ordering Information

Description	Color	UPC #	Catalog No.
USOC Keystone RJ25 Jack, 110 Termination	Office White	662620832340	HXJU8OW

### Listings

8-Position USOC Compliant  
 Mechanical TIA-568-C.2  
 UL Listed 1863  
 CSA Certified

### Specifications

Nose Contact	Beryllium copper with precious metal plating with nickel under-plating
IDC Contact	Phosphor bronze with 100 micro-inch tin lead 60/40 plating over nickel under plating
Housing	High impact thermoplastic (UL 94 V-0)

### Performance

#### Application

Phone  
 DSL

#### Electrical

8-Position USOC Compliant

#### General Information

Icon Compatible Supporting 606-B requirements  
 100% factory tested.



#### Mechanical

Contact performance confirmed over the full range of ISO/FCC compliant plug dimensions

Nose contact mating cycles RJ45: 2000

IDC contact termination: 10X

Keystone latching force: 25 lbs.

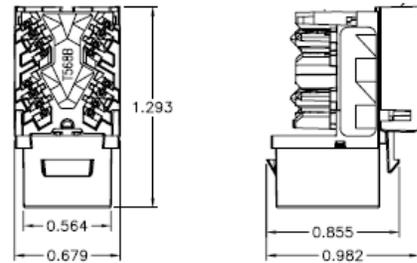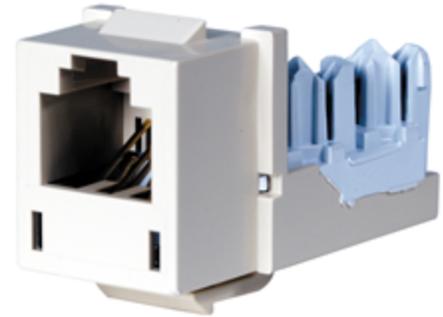

### Accessories

1-punch tool	TX4P
Ascent termination puck	HXTP25
Dust Cover	HXJDC25

### Resources

Customer Drawings  
 eCatalog  
 Specification Text Division 17