

- RJ-25 USOC (RJ-25) Jack
- Exclusive 1-Punch Termination Reduces Termination Time by 75%
- Mating Cycles Exceed Industry Standard by Four Times
- Bulk Packaging Reduces Excess Waste on the Job

Features

- HPW Icon compatible
- IDC towers have an inner blade to assist in pair splitting without performance disruption.
- Small form factor allows more jacks in devices without restriction or constraint.

Ordering Information

Description	Color	UPC #	Catalog No.
USOC Keystone RJ25 Jack, 110 Termination	Almond	662620204697	HXJUAL

Listings

6-Position USOC Compliant
 Mechanical TIA-568-C.2
 UL Listed 1863
 CSA Certified

Specifications

Nose Contact	Beryllium copper with precious metal plating with nickel under-plating
IDC Contact	Phosphor bronze with 100 micro-inch tin lead 60/40 plating over nickel under plating
Housing	High impact thermoplastic (UL 94 V-0)

Performance

Application

Phone
 DSL

Electrical

6-Position USOC Compliant

General Information

Icon Compatible Supporting 606-B requirements
 100% factory tested.



Mechanical

Contact performance confirmed over the full range of ISO/FCC compliant plug dimensions

Nose contact mating cycles RJ11/12/14/25: 2000

IDC contact termination: 10X

Keystone latching force: 25 lbs.

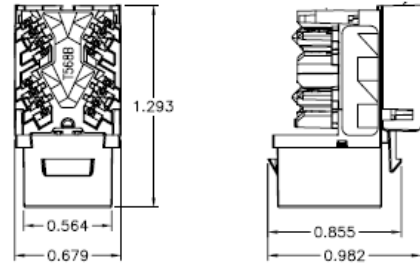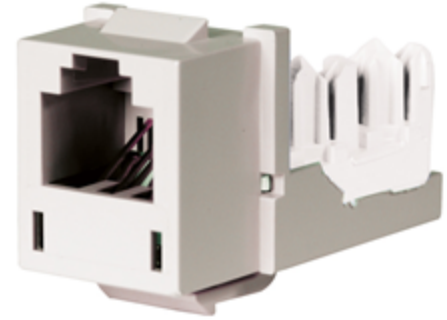

Accessories

1-punch tool	TX4P
Ascent termination puck	HXTP25
Dust Cover	HXJDC25

Resources

Customer Drawings
 eCatalog
 Specification Text Division 17