

HUBBELL  
**Xcelerator**  
 Xcelerator USOC Jack

HUBBELL  
**Advantage**

- RJ-25 USOC (RJ-25) Jack
- Exclusive 1-Punch Termination Reduces Termination Time by 75%
- Mating Cycles Exceed Industry Standard by Four Times
- Bulk Packaging Reduces Excess Waste on the Job

**Features**

- HPW Icon compatible
- IDC towers have an inner blade to assist in pair splitting without performance disruption.
- Small form factor allows more jacks in devices without restriction or constraint.

**Ordering Information**

Description	Color	UPC #	Catalog No.
USOC Keystone RJ25 Jack, 110 Termination	Light Almond	662620285016	HXJULA

**Listings**

6-Position USOC Compliant  
 Mechanical TIA-568-C.2  
 UL Listed 1863  
 CSA Certified

**Specifications**

Nose Contact	Beryllium copper with precious metal plating with nickel under-plating
IDC Contact	Phosphor bronze with 100 micro-inch tin lead 60/40 plating over nickel under plating
Housing	High impact thermoplastic (UL 94 V-0)

**Performance**

**Application**

Phone  
 DSL

**Electrical**

6-Position USOC Compliant

**General Information**

Icon Compatible Supporting 606-B requirements  
 100% factory tested.

**Mechanical**




Contact performance confirmed over the full range of ISO/FCC compliant plug dimensions

Nose contact mating cycles RJ11/12/14/25: 2000

IDC contact termination: 10X

Keystone latching force: 25 lbs.

# HUBBELL

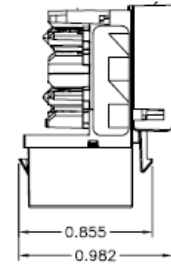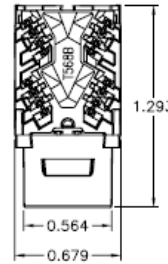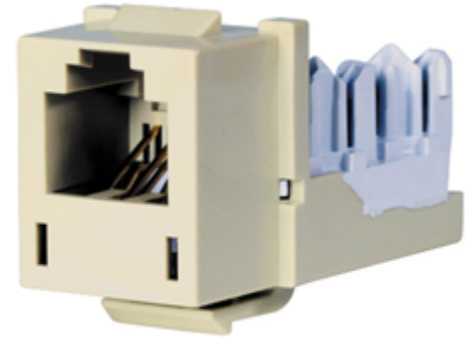

**Accessories**

1-punch tool	TX4P
Ascent termination puck	HXTP25
Dust Cover	HXJDC25

**Resources**

Customer Drawings  
 eCatalog  
 Specification Text Division 17

