

Mounted Zone Cabling Enclosures and Brackets

Industrial ReBox Enclosure for User Configuration

NEMA 4/12 ReBox Enclosure

HUBBELL

Features

- Continuous plasma-welded seams provide a seal to protect equipment from water intrusion
- Perforated rear panel allows for user configured installation of equipment and cable management
- Three-Point locked twist handle secures and applies pressure on door gasket for a water-tight seal

Ordering Information

NEMA Rating	Finish	Catalog Number	UPC Number
4 / 12	Gray powder coated	IR221UG	662620656625




Listings

NEMA Rated 4 / 12
EIA/ECA-310-E Universal Mounting Pattern
UL Listed

Specifications

Material	Carbon Steel
Gauge	14
Finish	Light Gray
NEMA Rating	4 / 12
Rail Type	#12-24 Threaded
Rack Units	9

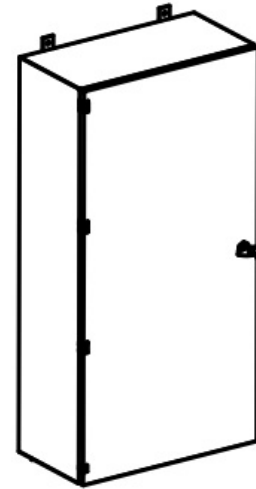

Dimensions- inches (mm)

A	24" (610)
B	24" (610)
C	12.9" (328)

Accessories

18" foot Kit	IRF1812
Screw Mount Velco	MCCMV9BS10
Heater Thermostat	CTKH
250W Heater	IRH250
#12-24 Screws	1224RRSCRW20

Online Resources

Customer Use Drawing
eCatalog
Product Guide