

Mounted Zone Cabling Enclosures and Brackets Industrial ReBox Enclosure with Equipment Mounting Brackets

NEMA 4/12 ReBox Enclosure

HUBBELL

Features

- Continuous plasma-welded seams provide a seal to protect equipment from water intrusion
- ReBox lanced rear panel allows for use of ReBox mounting brackets and accessories
- Three-Point locked twist handle secures and applies pressure on door gasket for a water-tight seal

Ordering Information

NEMA Rating	Finish	Catalog Number	UPC Number
4 / 12	Gray powder coated	IR321PG	662620656663

Listings

NEMA Rated 4 / 12
EIA/VECA-310-E Universal Mounting Pattern
UL Listed

Specifications


Material	Carbon Steel
Gauge	14
Finish	Light Gray
NEMA Rating	4 / 12
Rail Type	#12-24 Threaded
Rack Units	9

Accessories

18" foot Kit	IRF1812
5U Bracket	REKZ
Heater Thermostat	CTKH
250W Heater	IRH250
#12-24 Screws	1224RRSCRW20

Online Resources

Customer Use Drawing
eCatalog
Product Guide

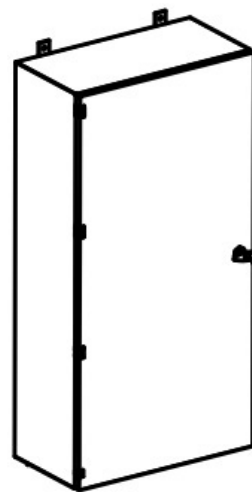

Dimensions- inches (mm)

A	36" (914)
B	24" (610)
C	12.9" (328)

