

# Mounted Zone Cabling Enclosures and Brackets Industrial ReBox Enclosure with Equipment Mounting Brackets

## NEMA 4/12 ReBox Enclosure

# HUBBELL

### Features

- Continuous plasma-welded seams provide a seal to protect equipment from water intrusion
- Three-Point locked twist handle secures and applies pressure on door gasket for a water-tight seal
- Plywood back panel allows for flexible mounting of equipment and cable management

### Ordering Information

NEMA Rating	Finish	Catalog Number	UPC Number
4 / 12	Gray powder coated	IR322PG	662620656366

### Listings

NEMA Rated 4 / 12  
EIA/ECA-310-E Universal Mounting Pattern  
UL Listed

### Specifications


Material	Carbon Steel
Gauge	14
Finish	Light Gray
NEMA Rating	4 / 12
Rail Type	#12-24 Threaded
Rack Units	19

### Accessories

12" foot Kit	IRF1224
5U Bracket	REKZ
Heater Thermostat	CTKH
250W Heater	IRH250
#12-24 Screws	1224RRSCRW20

### Online Resources

Customer Use Drawing  
eCatalog  
Product Guide

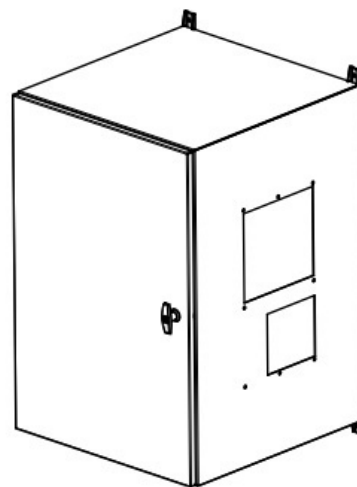

### Dimensions- inches (mm)

A	36" (914)
B	24" (610)
C	24" (610)

