

Racks

iFrame Column System

Raised Floor Column Kit



Features

- Rack mounting and integrated cable management in every column
- Columns mount independent to allow for easy installation of network equipment
- Solid weldment allow for easy addition and expansion

Ordering Information

Rack Units	iFrame Width	Catalog Number	UPC
45	5"	IS7RFM6	662620284873

Listings

UL 1863
EIA/ECA-310-E Universal Mounting Pattern

Specifications

Material	Steel
Color	Black
Rack Units	45
Mounting	M6 Cage Nut
Floor Type	12" Raised Floor

Characteristics


Load Capacity	1,400 lb per column
Equipment	Supports 19" EIA wide rack-mount equipment
Thread Holes	M6 Cage Nut
Rack Units	Numbered

Accessories

3" Cable management spools	ICKSS
1U Horizontal cable manager with cover	HM17C
2U Horizontal cable manager with cover	HM27C
15A Powerstrip	HPWPWR
Horizontal rack bonding bus bar	HBBBHR19KT

Online Resources

Customer Drawing
Customer Use Drawing
eCatalog

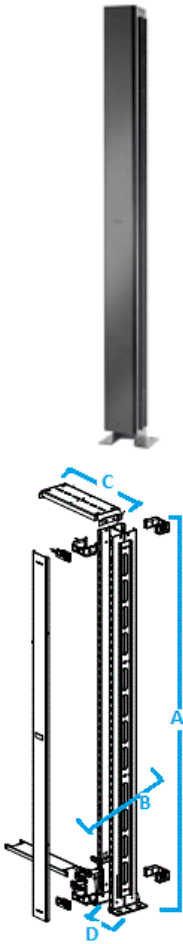

Dimensions- inches (mm)

A	96.3" (2447)
B	14.2" (361)
C	19.6" (478)
D	4.75" (121)