

# HDMI High-Definition 110 Video Extender

- Extend HDMI Signal Over UTP
- 110 Termination Reduces Installation Time
- HD High Definition Video 1080p
- Customize Point to Point Runs on Site

## Features

- Locate a display device up to 150' away is as simple as pulling 2 additional UTP cables to a drop
- Supplied as a kit with a "Source" and "Display" frame/module and a 5-volt DC power supply.
- Terminate with Category 5e, 6 or 6A UTP plenum or non-plenum cable

## Ordering Information

Description	Color	UPC Number	Catalog Number
Decorator Frame, HDMI, 110 Termination	Office White	662620300030	ISFH110OW

## Listings

HDMI Version 1.3  
 HDCP Compliant  
 UL 1863 Modules and Frames  
 C-UL-us I.T.E. Listed Power Supply  
 RoHS Compliant

## Specifications

Nose Contact	19-Pin, Type A, Female Connector, Gold Plated 2u"
IDC Contact	Phosphor bronze with tin plating over nickel under plating
Material	High impact thermoplastic

## Performance

### Application

Type A is electrically compatible with single-link DVI-D.  
 Video signal: 480i, 480p, 576i, 576p, 720p, 1080i, 1080p  
 Audio Signal: PCM, DVD-Audio, Super Audio CD, Dolby True HD, DTS-HD Master Audio

### Electrical

Distance Limitations:	45 meters (150') = Cat 6A
Hubbell Approved Cable	40 meters (130') = Cat 6
	35 meters (115') = Cat 5e

### General Information

Flat Panel TVs, Monitors, Projectors, White/Smart Boards, Game Consoles, Component and Portable Devices, Computers and Laptop


LED on the iStation HDMI Video Extender lets you know that power and a signal are working properly.

100% factory tested.

Important: Always allow for clearance behind connection location to ensure for proper bend radius with HDMI cable assemblies.

### Mechanical

Nose contact: 250 Insertions  
 IDC contact termination: 10X

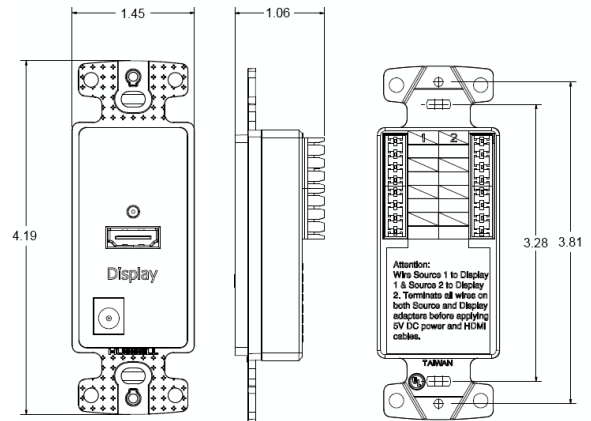

## Accessories

HDMI, 3ft Patch Cord, 24AWG, Black	HDPC03BK
HDMI, 6ft Patch Cord, 24AWG, Black	HDPC06BK
Decorator Plate, 1-Gang, White	NP26W