

**OptiChannel
Fiber Accessory
Plug and Play Cassette**

HUBBELL

Features

- Compact Universal Design
- Ten Gigabit Ethernet Assurance
- Quick and Easy Plug-n-Play Installation

Ordering Information

Description	Color	Catalog Number	UPC
Fiber Optic Cassettes, LV-MT, OM2 Fiber/125, 24-Fiber Strands, OM4 Fiber	Aqua	OCLCD50G4	662620304410

Listings


Telcordia GR-326-CORE
TIA-568-C.3
TIA-604-FOCIS

Specifications

Material	Ceramic
Fiber Size	250 Micron
Fiber Type	OM4
Style	LC Duplex 24F
Polarity	Type A
Repeatability	0.1 dB
Service Life	500 matings
Temperature Rating	0 °C to 70 °C

Performance

Optical	
Total Insertion Loss	Less than 1.5dB (test data included)

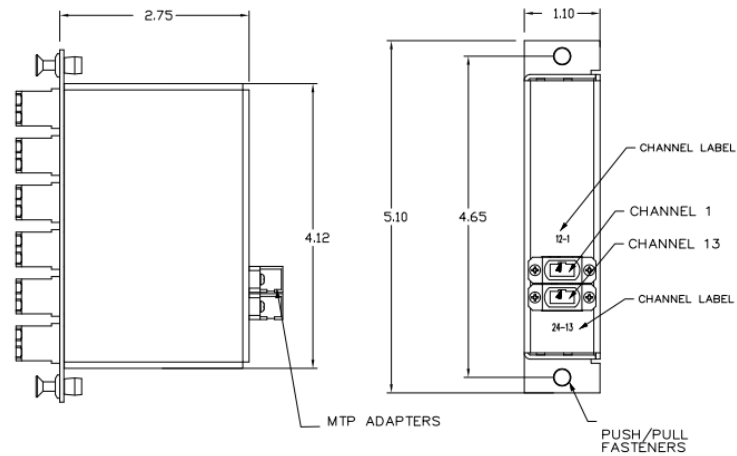

Hubbell Premise Wiring