

Racks

Server Frame 4-Post

42" Depth, #12-24 Threaded

HUBBELL

Features

- Steel construction provides strength for heavy server and network equipment loading
- Ladder tray mounting provisions designed into top cross members
- Each rack unit numbered

Ordering Information

Rack Units	Finish	Catalog Number	UPC
45	Black powder coat	SF841942T	662620249094

Listings

UL 1863
EIA/ECA-310-E Universal Mounting Pattern

Specifications

Height	84" (2134)
Depth	42" (1067)
Width	20" (514)
Hole Type	#12-24 Threaded
Material	Steel
Gauge	12 ga

Characteristics


Load Capacity	2,000 lb
Equipment	Supports 19" EIA wide rack-mount equipment
Thread Holes	#12-24
Rack Units	Numbered

Accessories

Isolation Pad	HRRP
#12-24 Screws	1224RRSCRW20
1U Horizontal cable manager	HS13C
2U Horizontal cable manager	HS23C
6" Wide vertical cable manager	VS76H

Online Resources

Customer Drawing
Customer Use Drawing
eCatalog

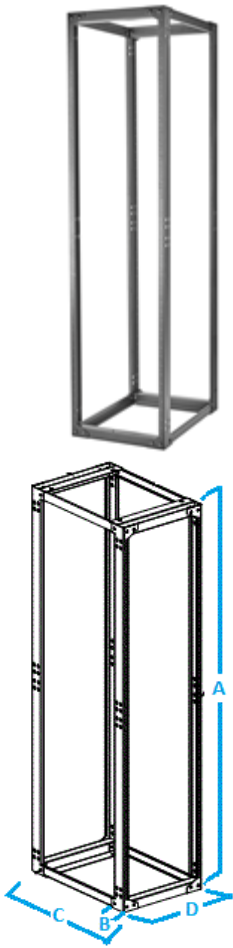

Dimensions- inches (mm)

A	84" (2134)
B	3" (76)
C	42" (1067)
D	20.2" (513)