

OptiChannel
Simplex Fiber Patch Cords, Riser
LCA to LCA, Singlemode, OS2

HUBBELL

Features

- Precision Zirconia Ferrule, APC Polish
- 100% Tested, Heat Cured Epoxy Termination
- Available in Lengths 1 to 5, 10 meters
- Custom Lengths Quoted to Order

Ordering Information

Description	Cable Type	Catalog Number	UPC
Fiber Patch Cord, Riser, Simplex, LC/APC to LC/APC, OS2, 1M	Simplex Jacket, Yellow	SFRCLCALCAS1SM	662620614083

Standards

TIA-568.3
TIA-604-FOCIS
Telcordia GR-326-CORE
TIA-492CAAB (OS2, Bend Tolerant)
ANSI/ICEA S-83-596
TIA-598


Specifications

Overall Length	1 meter (3.28 ft)
Ferrule Material	Zirconia Ceramic
Cable Diameter	1.6 mm to 2.0 mm
Mated Pair Insertion Loss	< 0.35 dB (0.15 dB Typical)
Mated Pair Return Loss	> 65 dB
Polarity	A

Performance

Mechanical

Mating Durability	500 Cycles, < 0.75dB
Minimum Bend Radius	25 mm (1.0 in.)
Operating Temperature Range	0C to 70C (32F to 158F)
Tensile Rating, Short Term	11.24 Lb (50 N)

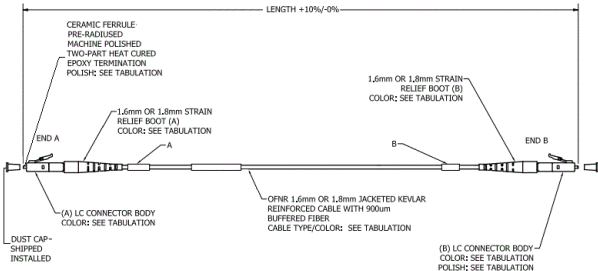

CABLE TYPE	CABLE COLOR	POLISH	CORN. COLOR (A)	BOOT COLOR (A)	POLISH (B)	BOOT COLOR (B)	BOOT COLOR (B)
OS2, OS2	YELLOW	APC	GREEN	GREEN	APC	GREEN	GREEN

Applications

10 Gbps/25 Gbps Fiber Channel
Backbone/Horizontal Distribution Interconnect
Data Center Equipment Interconnect

Accessories

Fiber Microscope, 200X	OFSCOPE2
Fiber Cleaning Kit	OFCLEANKT1
Fiber Wipes Dispenser, 90 Sheets	OFWIPES90
Fiber Cleaning Fluid, 3 Oz.	OFCLEANER3OZ

Online Resources

eCatalog

