

OptiChannel  
**Simplex Fiber Patch Cords, Riser**  
**LC to FC, Singlemode, OS2**



**Features**

- Precision Zirconia Ferrule, UPC Polish
- 100% Tested, Heat Cured Epoxy Termination
- Available in Lengths 1 to 5, 10 meters
- Custom Lengths Quoted to Order

**Ordering Information**

Description	Cable Type	Catalog Number	UPC
Fiber Patch Cord, Riser, Simplex, LC to FC, OS2, 2M	Simplex Jacket, Yellow	SFRCLCFCs2SM	662620613970

**Standards**

TIA-568.3  
 TIA-604-FOCIS  
 Telcordia GR-326-CORE  
 TIA-492CAAB (OS2, Bend Tolerant)  
 ANSI/ICEA S-83-596  
 TIA-598

**Specifications**

Overall Length	2 meters (6.56 ft)
Ferrule Material	Zirconia Ceramic
Cable Diameter	1.6 mm to 2.0 mm
Mated Pair Insertion Loss	< 0.35 dB (0.15 dB Typical)
Mated Pair Return Loss	> 55 dB
Polarity	A

**Performance**

Mechanical	
Mating Durability	500 Cycles, < 0.75dB
Minimum Bend Radius	25 mm (1.0 in.)
Operating Temperature Range	0C to 70C (32F to 158F)
Tensile Rating, Short Term	11.24 Lb (50 N)

**Applications**


10 Gbps/25 Gbps Fiber Channel  
 Backbone/Horizontal Distribution Interconnect  
 Data Center Equipment Interconnect

**Accessories**

Fiber Microscope, 200X	<b>OFSCOPE2</b>
Fiber Cleaning Kit	<b>OFCLEANKT1</b>
Fiber Wipes Dispenser, 90 Sheets	<b>OFWIPES90</b>
Fiber Cleaning Fluid, 3 Oz.	<b>OFCLEANER3OZ</b>

**Online Resources**

eCatalog

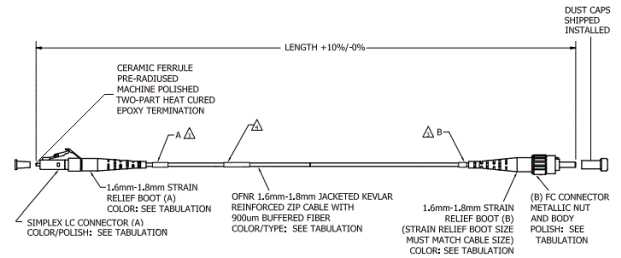

CABLE TYPE	CABLE COLOR	POLISH(A)	CONN. COLOR (A)	BOOT COLOR (A)	POLISH (B)	CONN. COLOR (B)	BOOT COLOR (B)
19/25 OS2	YELLOW	UPC	BLUE	WHITE	UPC	METALLIC	BLUE

