

Stainless Steel Wall Mount Phone Plates

Features

- Studs Accommodate Any Standard Wall Phone
- Comes With Keystone Jack
- Manufactured From Type 430 Stainless Steel, Brush Finish

Ordering Information

Description	Color	Catalog No.	UPC
iStation Stainless Steel Wall Mount Phone Plate, Single Gang, Flush Jack	Gray	SP10GF	662620553887

Listings

UL and cUL Listed 1863
10GBASE-T Application Assurance
Mechanical: Verified to TIA-568-C.2
Mechanical TIA-568-C.2
RoHS Compliant

Specifications

Nose Contact	Beryllium copper with precious metal plating with nickel under-plating
IDC Contact	Phosphor bronze with 100 micro-inch tin lead 60/40 plating over nickel under plating
Jack Housing	High-impact thermoplastic (UL 94V-0)
Packaging	Carton 100% recycled material - bag 85% recycled material

Performance

Electrical

Qualified to support 10GBASE-T
Qualified to 150% of 802.3bt PoE Current Level

General Information


Backward compatible to Category 6, & 5e
100% factory tested

Mechanical

Nose Contact Mating Cycles: 2000
IDC Contact Termination: 10x
Keystone Latching Force: 25 lbs.

Applications

IEEE 802.3an 10GBASE-T
IEEE 802.3bt 4PPoE Power over Ethernet

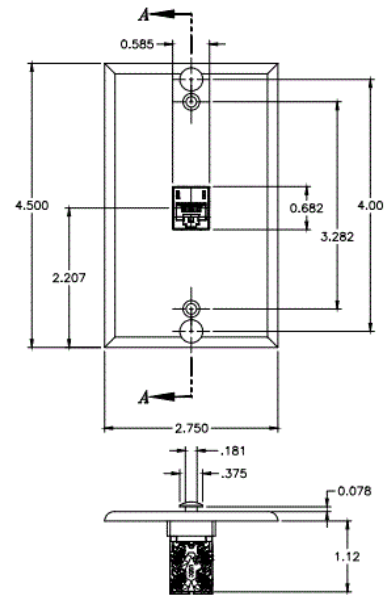

Accessories

1-Punch Tool	TX4P
Category 6A Patch Cord	HC6AB03
Dust Cover	HXJDC25
Ascent Termination Puck	HJTP6A25
Category 6A Cable	C6ASPB

Online Resources

eCatalog