

## Stainless Steel Wall Mount Phone Plates

### Features

- Studs Accommodate Any Standard Wall Phone
- Comes With Keystone Jack
- Manufactured From Type 430 Stainless Steel, Brush Finish

### Ordering Information

Description	Color	Catalog No.	UPC
iStation Stainless Steel Wall Mount Phone Plate, Single Gang, Recessed Jack	Gray	SP10GR	662620553894

### Listings

UL and cUL Listed 1863  
10GBASE-T Application Assurance  
Mechanical: Verified to TIA-568-C.3  
Mechanical TIA-568-C.3  
RoHS Compliant

### Specifications

Nose Contact	Beryllium copper with precious metal plating with nickel under-plating
IDC Contact	Phosphor bronze with 100 micro-inch tin lead 60/40 plating over nickel under plating
Jack Housing	High-impact thermoplastic (UL 94V-0)
Packaging	Carton 100% recycled material - bag 85% recycled material

### Performance

#### Electrical

Qualified to support 10GBASE-T  
Qualified to 150% of 802.3bt PoE Current Level

#### General Information


Backward compatible to Category 6, & 5e  
100% factory tested

#### Mechanical

Nose Contact Mating Cycles: 2000  
IDC Contact Termination: 10x  
Keystone Latching Force: 25 lbs.

### Applications

IEEE 802.3an 10GBASE-T  
IEEE 802.3bt 4PPoE Power over Ethernet

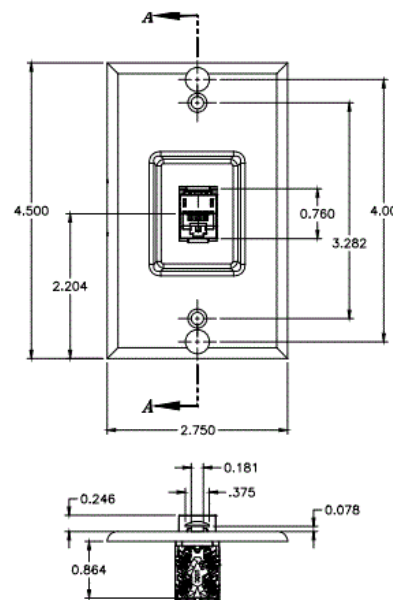

### Accessories

1-Punch Tool	TX4P
Category 6A Patch Cord	HC6AB04
Dust Cover	HXJDC26
Ascent Termination Puck	HJTP6A26
Category 6A Cable	C6ASPB

### Online Resources

eCatalog