




## Cable, Cat5E, Riser Rated, 300MHz, Relex, Orange

By Hubbell Premise Wiring  
Catalog Number C5ERROR

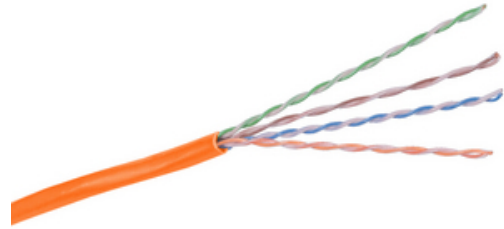

Cable, SPEEDGAIN, Category 5e, Riser/REELEX, Orange.

### Application

Riser

### General

Construction	Copper/Insulation Eccentricity Shall Be 90% Minimum
Data Transfer Rate	1GbE
EU RoHS Indicator	Yes
Item Type	SPEEDGAIN Category 5e UTP Cable
Material - Jacket	PVC
Temperature Rating	-20oC to +50oC (-4oF to +122oF)
UPC	662620288079

### Electrical Ratings

Impedance	100
-----------	-----

### Conductor Related

Conductor Size	#24 AWG
Conductor Type	Solid Bare Copper
Nema Color	Orange
Pairs Or Conductor	4-Pair

### Logistics

Carton Quantity	1000
-----------------	------

### Product Assets

[Catalog Page - Premise Catalog Page E-8](#)



A proud member of the Hubbell Family.