




Copper Solutions, Cable, NEXTSPEED, 10GBE, Plenum Rated, Spool, Orange

By Hubbell Premise Wiring
Catalog Number [C6ASPOR](#)

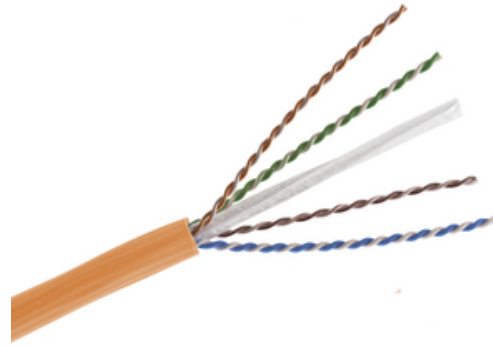

Copper Solutions, Cable, NEXTSPEED, 10GBE, Plenum Rated, Spool, Orange.

Application

Plenum

General

Construction	Copper/Insulation Eccentricity Shall Be 90% Minimum
Data Transfer Rate	10GbE
EU RoHS Indicator	Yes
Item Type	NEXTSPEED Category 6A UTP Cable
Material - Jacket	Low Smoke PVC
Temperature Rating	-20oC to +50oC (-4oF to +122oF)
UPC	662620288017

Electrical Ratings

Capacitance	5.6 nF/100 Meters @ 1 kHz
Impedance	100

Conductor Related

Conductor Size	#23 AWG
Conductor Type	Solid Bare Copper
Nema Color	Orange
Pairs Or Conductor	4-Pair

Logistics

Carton Quantity	1000
-----------------	------

Product Assets

[Catalog Page - Premise Catalog Page E-4](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
PREM_CA-C6ASPOR-SPEC-EN | REV 5/2023